


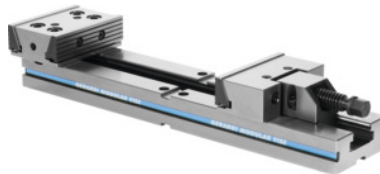

Modular vice long, Jaw width A: 150/3mm



Order data

Order number	362105 150/3
GTIN	2050001774286
Item class	35G

Description

Version:

- Simple mechanical actuation (up to 3.5 t).
- Easy adjustment of jaw opening.
- Machine vice with pull-down jaws.
- Case-hardened HRC 60.
- Parallelism 0.02 mm.

Supplied with:

Supplied with pull-down jaws, 1 workpiece backstop, 2 T-nuts No. 362160 size 16/16, 1 clamping wrench, 1 cross-bar wrench.

Note:

See No. 362160 for other T-nuts.

Technical description

Base body height G	50 mm
Overall length L	680 mm
Transverse tenon slot n	16 mm
Weight	35 kg
Clamping range b	460 mm
Colour code for suitable accessories	Gerardi 150
Jaw height C	50 mm

Longitudinal tenon slot l	16 mm
Jaw width A	150 mm
maximum clamping force at 80 Nm	30 kN
Series	Gerardi 150
Type of product	Machine vice

Accessories

Modular element fixed (piece) for jaw width 150 mm	362150 150
Prismatic top jaw (piece) for jaw width 150 mm	362135 150
Smooth front jaw, hard (piece) for jaw width 150 mm	362147 150
Pair of clamps for jaw width 150 mm	362120 150
Longitudinally serrated front jaw (piece) for jaw width 150 mm	362146 150
Pair of T-nuts T-slot dimension B / keyway 12/16 mm	362160 12/16
Pair of T-nuts T-slot dimension B / keyway 14/16 mm	362160 14/16
Movable jaw (piece) for jaw width 150 mm	362143 150
Pair of T-nuts T-slot dimension B / keyway 16/16 mm	362160 16/16
Modular element movable (piece) for jaw width 150 mm	362145 150
Complete clamping element (piece) for jaw width 150 mm	362144 150
Pair of T-nuts T-slot dimension B / keyway 20/16 mm	362160 20/16
Smooth front jaw, soft (piece) for jaw width 150 mm	362148 150
Pair of T-nuts T-slot dimension B / keyway 18/16 mm	362160 18/16
Square top jaw (piece) for jaw width 150 mm	362130 150
Centre jaw (piece) for jaw width 150 mm	362142 150
Prismatic jaw (piece) for jaw width 150 mm	362125 150