


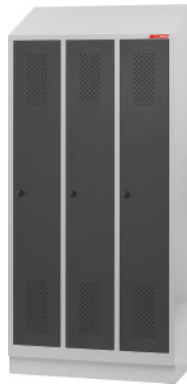

Garment locker with sloping roof, fitted base and security twist bar lock, Number of compartments: 3



Order data

Order number

949621 3

GTIN

Item class

92S

Description

Version:

The body has a sloping roof, so that no objects can be placed on top of the locker. Compartment width 300 mm with welded-in hat shelf. Hanger rail has 3 sliding clothes hooks. Door with diamond pattern ventilation holes and pressed-in label frame. Choice between plastic feet or fitted base.

With rotary catch; up to size 40 can be locked with padlock (not included).

Standard:**DIN 4547****Colour:**

Body light grey RAL 7035, doors anthracite RAL 7016 **powder-coated**. No special paint finishes available.

Note:

According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

Technical description

usable width of each compartment	220 mm
Ventilation slots in the door	yes
Height at the rear	2000 mm
for padlock	yes
Shelf width	220 mm
Cabinet fronts	Plain sheet metal swing door
Number of compartments	3
suitable for integral helmets	yes
Sloping roof	yes
usable depth of each compartment	465 mm
Lock version	Security twist bar lock
Support cabinet version	Fitted base
Depth	500 mm
Number of clothes rails	1
Number of fixed shelves	1
Weight	70 kg
Height at the front	1800 mm
Standard	DIN 4547
usable height of each hat compartment with sloping roof	360 - 530 mm
for padlock with shackle Ø up to	6 mm
usable height of each clothing compartment	1260 mm
Width	900 mm
Storage shelf depth	465 mm
Special paints available	no
Material thickness	0.8 mm
Door opening angle	110 degrees
Colour selection	RAL 7035, RAL 7016, RAL 5005
Type of product	Locker

Accessories

Clothes hanger pieces 10	949775 10
Precision cylinder lock with tall shackle individual keys Body Ø 40 mm	085875 40
Clothes hanger pieces 1	949775 1