


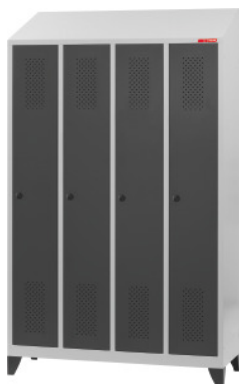

## Garment locker with sloping roof, plastic feet and security twist bar lock, Number of compartments: 4



### Order data

Order number

949623 4

GTIN

Item class

92S

### Description

**Version:**

The body has a sloping roof, so that no objects can be placed on top of the locker. Compartment width 300 mm with welded-in hat shelf. Hanger rail has 3 sliding clothes hooks. Door with diamond pattern ventilation holes and pressed-in label frame. Choice between plastic feet or fitted base.

With rotary catch; up to size 40 can be locked with padlock (not included).

**Standard:****DIN 4547****Colour:**

Body light grey RAL 7035, doors signal blue RAL 5005 **powder-coated**. No special paint finishes available.

**Note:**

According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

### Technical description

Sloping roof	yes
for padlock	yes
usable depth of each compartment	465 mm
Shelf width	220 mm
Width	1190 mm
Ventilation slots in the door	yes
Height at the front	1800 mm
Number of fixed shelves	1
Number of clothes rails	1
Support cabinet version	Plastic feet
Depth	500 mm
Standard	DIN 4547
Cabinet fronts	Plain sheet metal swing door
suitable for integral helmets	yes
usable height of each clothing compartment	1260 mm
Storage shelf depth	465 mm
usable height of each hat compartment with sloping roof	360 - 530 mm
Height at the rear	2000 mm
Special paints available	no
for padlock with shackle Ø up to	6 mm
Lock version	Security twist bar lock
Weight	83 kg
Number of compartments	4
usable width of each compartment	220 mm
Material thickness	0.8 mm
Door opening angle	110°
Colour selection	RAL 7035, RAL 7016, RAL 5005
Type of product	Locker

---

**Accessories**

Clothes hanger pieces 10	949775 10
Additional shelf for shoes Compartment width 300 mm	949760 300
Plastic tray for shoes Type 1	949761 1
Precision cylinder lock with tall shackle individual keys Body Ø 40 mm	085875 40
Mirror Type 1	949770 1
Clothes hanger pieces 1	949775 1