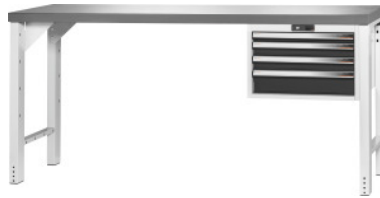


Garant GRIDLINE

Vario workbench with drawer casing 24G, height 950 mm, Eluplan worktop, dark, 20×20G, Worktop length: 2000/4mm**Order data**

| | |
|--------------|---------------|
| Order number | 922677 2000/4 |
| GTIN | 4062406084752 |
| Item class | 9GG |

Description**Version:**

Workbench in sturdy steel construction. Support legs 50 mm wide with cross bracing. Feet with plastic pads, do not damage the floor. With 1 pair of stabilising plates for stiffening. Drawer casing 24G can be locked centrally with cylinder lock. **100% full extension drawers** with differential runners and 75 kg load capacity.

Fitted with:

Drawer front height, mm: 50, 75, 75, 125

Supplied with:

2 × support legs, 1 × pair of stabilising plates, drawer casing with drawers, worktop.

Optional extras:

Additional accessories such as manual height adjustment, wheels, side panels, etc. can be found under GridLine individual components in Group 92.

Colour:

Casing body, support legs and drawer body RAL 7035 light grey, drawer fronts RAL 7016 anthracite, **powder-coated. Drawer body not configurable, always RAL 7035 light grey.**

Note:

Supplied for self-assembly, saving freight costs. Delivered unassembled.

Technical description

| | |
|---|--------|
| Workbench/desk load capacity - maximum distributed load (on wood) | 400 kg |
|---|--------|

| | |
|--|--|
| Drawer body height | 400 mm |
| Drawer usable width in G | 20 |
| Worktop thickness | 50 mm |
| Drawer usable depth | 500 mm |
| Number of drawers | 4 |
| Drawer body depth | 650 mm |
| Worktop length | 2000 mm |
| Drawer usable area in G | 20×20 |
| Drawer body usable height | 325 mm |
| Drawer usable width | 500 mm |
| Weight | 145 kg |
| Drawer body width | 600 mm |
| Height | 950 mm |
| Series | vario |
| Drawer usable depth in G | 20 |
| Worktop depth | 750 mm |
| Design version | Steel hollow section construction |
| Material thickness | 1 mm |
| Workbench height | 950 mm |
| Drawer/pull-out shelf load capacity | 75 kg |
| Insert thickness | 50 mm |
| Drawer runner extension (partial/full extension) | 100 % |
| Cylinder lock | modular lock barrel |
| Colour selection | RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003 |
| Product name attribute | 20×20G |
| Type of product | Workbench |

Accessories

| | |
|--|--------------|
| Lock plate for GridLine Type KO21 | 914227 KO21 |
| Drawer Drawer front height 125 mm | 927800 125 |
| Drawer Drawer front height 50 mm | 927800 50 |
| Drawer Drawer front height 75 mm | 927800 75 |
| Support leg Height 900 mm | 927000 900 |
| Stabilising plate Type 1 | 927122 1 |
| Drawer casing 24G with drawers Height / number of drawers 400/4 | 927600 400/4 |
| Worktopwith dark grey plastic coating (Eluplan) Worktop length 2000 mm | 926241 2000 |