


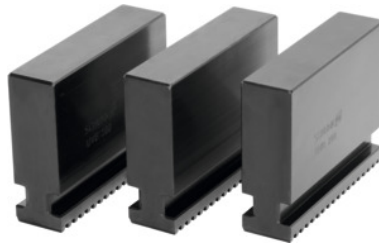

Soft monoblock jaw set, 3 pieces straight serration, for chuck type: 160



Order data

Order number	313227 160
GTIN	2050001929198
Item class	33T

Description

Version:

Serrations hardened and ground.

Application:

As the jaws can be changed or adjusted to the required diameter **in just a few seconds**, it is useful to have several jaw sets on hand ready for use at the machine. **This minimises set-up times.** The jaw units consist for example of several sets of base jaws with soft top jaws, which can be machined out to the required diameters. This rationalisation method is not only necessary for NC machines but also important for every lathe type.

Material:

C45, annealed

Suitable for:

Schunk self-centring chucks No. 313115; 313117; 313135; 313137, Röhм self-centring chucks Duro No. 313120; 313140 and other self-centring chuck systems.

Note:

- **Hard top and stepped jaws purchased subsequently must be ground internally in the chuck for concentricity and run-out.**
- **Please check the serrations when matching to lathe chucks.**

Technical description

Length L	65 mm
Height H	55.5 mm

Width B	20 mm
for chuck type	160 mm
Type of product	Self-centring chuck jaws