


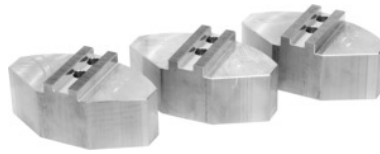

Segment jaws set, 3 pieces, Aluminium, for chuck type: 315



Order data

Order number	313737 315
GTIN	2050001929761
Item class	33T

Description

Version:

Precision milled slots and **precision ground** serrations.

Application:

All-round low-distortion clamping.

Suitable for:

Heavy-duty chucks from Schunk, Röhms and other heavy-duty chuck manufacturers.

Optional extras:

T-nuts No. 313505 – 313605.

Note:

- **When fitting to a chuck, please check serrations, slot width (D), and hole spacing (a, b).**
- **Aluminium top jaws on request.**

Technical description

for chuck type	315 mm
Hole centre spacing a	45 mm
Slot width D	21 mm
Length L	117 mm
Height H	78 mm
Width B	240 mm
Bore spacing b	30 mm

suitable for colour code	Schunk heavy-duty chucks and jaws
Type of product	Heavy-duty lathe chuck jaws