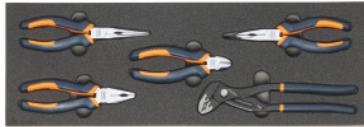


Garant**Pliers set, Number of tools: 5****Order data**

Order number	954231 5
GTIN	4062406097271
Item class	91A

Description**Version:**

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. **Upper layer is anthracite**, the underlying **contrast colour is grey**, thereby indicating any missing tools.

Supplied with:

Rigid foam inlay, empty No. 952001 size 954231: 1 pc.
GARANT combination pliers No. 700940 size 180: 1 pc.
GARANT water pump pliers No. 706001 size 250: 1 pc.
GARANT snipe-nose pliers No. 713040 size 200: 1 pc.
GARANT snipe-nose pliers, angled No. 713440 size 200: 1 pc.
GARANT side cutter No. 724840 size 160: 1 pc.

Technical description

Depth	600 mm
Width in G	8
Depth in G	24
Width	200 mm
Number of tools	5
Weight	1.554 kg
Rigid foam quality LD45, thickness	30 mm

Degree of fill of a drawer in units	8×24
Type of product	Rigid foam inlay

Accessories

Rigid foam inlay for tool sets suitable for rigid foam set 954231	952001 954231
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706000 250
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706001 250
Snipe nose pliers, straight, chrome-plated, with grips overall length 200 mm	713040 200
Diagonal side cutter chrome-plated, with grips overall length 160 mm	724840 160
Snipe nose pliers, angled, chrome-plated, with grips overall length 200 mm	713440 200
Combination pliers, chrome-plated, with 2-component grips overall length 180 mm	700940 180