


PRYOR

**Interchangeable numeral and letter punch set normal script 0 - 9 and A - Z,
Character height: 1,5mm**

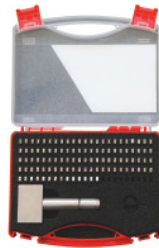

Order data

Order number	085480 1,5
GTIN	5022044020139
Item class	08W

Description

Version:

High precision punch holder for quick and efficient marking with **several letters and numbers at the same time.**

Application:

For punching into materials (e.g. identification plates, tools, machine parts etc.) with **strengths up to 1200 N/mm².**

Supplied with:

100 stamp types
12 spacers (font height 5 mm: 6 pieces)
1 pair of tweezers
1 hexagon L-wrench
1 holder
in a plastic box.

Spare part:

Individual type punches can be ordered under No. 085481 stating the desired font size / type (e.g. No. 085481 size 3/E).

Technical description

Number of punch types that can be used	12
Width of punch type	1.6 mm
Character height	1.5 mm
Length of punch holder	20 mm
Height of punch type	3.2 mm
Length of punch type	15.87 mm
Type of product	Hand punch

Accessories

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/& mm	085481 1,5/&
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/A mm	085481 1,5/A
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/V mm	085481 1,5/V
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5LEER mm	085481 1,5LEER
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/3 mm	085481 1,5/3
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/F mm	085481 1,5/F
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/- mm	085481 1,5/-
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/0 mm	085481 1,5/0
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/U mm	085481 1,5/U
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/1 mm	085481 1,5/1
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/M mm	085481 1,5/M

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/K mm	085481 1,5/K
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/C mm	085481 1,5/C
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/4 mm	085481 1,5/4
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/2 mm	085481 1,5/2
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/X mm	085481 1,5/X
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/Q mm	085481 1,5/Q
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/J mm	085481 1,5/J
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/Z mm	085481 1,5/Z
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/, mm	085481 1,5/,
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/D mm	085481 1,5/D
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/5 mm	085481 1,5/5
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/R mm	085481 1,5/R
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/N mm	085481 1,5/N
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/6 mm	085481 1,5/6
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5// mm	085481 1,5//
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/P mm	085481 1,5/P
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 1,5/T mm	085481 1,5/T
	085481 1,5/9

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/9 mm

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/l mm

085481 1,5/l

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/+ mm

085481 1,5/+

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/H mm

085481 1,5/H

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/8 mm

085481 1,5/8

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/W mm

085481 1,5/W

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/S mm

085481 1,5/S

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/Y mm

085481 1,5/Y

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/7 mm

085481 1,5/7

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/O mm

085481 1,5/O

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/L mm

085481 1,5/L

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/E mm

085481 1,5/E

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/B mm

085481 1,5/B

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/. mm

085481 1,5/.

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 1,5/G mm

085481 1,5/G