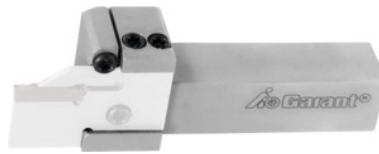


Garant
VARIO-LINE toolholder, right-hand, Shank height h: 32mm

Order data

Order number	273794 32
GTIN	4045197721440
Item class	21W

Description
Suitable for :

Blade carrier No. 273798.

Supplied with:

Including assembly screws.

Note:
 $L = L_1 + L_3$ (blade carrier).

 Functional width L_4 : 30 mm

 L_1 : 170 mm

 L_2 : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

Technical description

Shank height h	32 mm
Screw	279815 9 (TX25; 6.0 Nm)
Functional width L_4	30 mm
L_1	170 mm
L_2	24.5 mm
Application type	right-hand
Type of product	Clamping toolholder

Accessories

Clamping screw	279910
PrecisionBit for Torx®, shank E 6.3 Torx® profile TX10	674248 TX10
Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
Clamping screw Type 9	279815 9