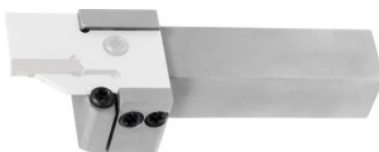


Garant**VARIO-LINE toolholder, left-hand, Shank height h: 20mm****Order data**

Order number	273795 20
GTIN	4045197721327
Item class	21W

Description**Suitable for :**

Blade carrier No. 273799.

Supplied with:

Including assembly screws.

Note: $L = L_1 + L_3$ (blade carrier).Functional width L_4 : 25 mm L_1 : 125 mm L_2 : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

Technical description

L_2	24.5 mm
Functional width L_4	25 mm
Screw	279815 9 (TX25; 6.0 Nm)
Shank height h	20 mm
L_1	125 mm
Application type	left-hand
Type of product	Clamping toolholder

Accessories

Clamping screw Type 9	279815 9
Clamping screw	279910
PrecisionBit for Torx®, shank E 6.3 Torx® profile TX10	674248 TX10
Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500