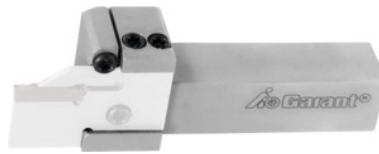


**Garant**
**VARIO-LINE toolholder, right-hand, Shank height h: 20mm**

**Order data**

Order number	273794 20
GTIN	4045197721099
Item class	21W

**Description**
**Suitable for :**

Blade carrier No. 273798.

**Supplied with:**

Including assembly screws.

**Note:**
 $L = L_1 + L_3$  (blade carrier).

 Functional width  $L_4$ : 25 mm

 $L_1$ : 125 mm

 $L_2$ : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

**Technical description**

Functional width $L_4$	25 mm
$L_1$	125 mm
Shank height h	20 mm
Screw	279815 9 (TX25; 6.0 Nm)
$L_2$	24.5 mm
Application type	right-hand
Type of product	Clamping toolholder

---

## Accessories

Clamping screw Type 9	279815 9
Clamping screw	279910
Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
PrecisionBit for Torx®, shank E 6.3 Torx® profile TX10	674248 TX10