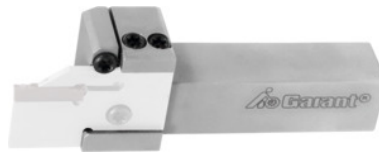


**Garant**
**VARIO-LINE toolholder, right-hand, Shank height h: 25mm**

**Order data**

Order number	273794 25
GTIN	4045197721303
Item class	21W

**Description**
**Suitable for :**

Blade carrier No. 273798.

**Supplied with:**

Including assembly screws.

**Note:**
 $L = L_1 + L_3$  (blade carrier).

 Functional width  $L_4$ : 30 mm

 $L_1$ : 150 mm

 $L_2$ : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

**Technical description**

Screw	279815 9 (TX25; 6.0 Nm)
$L_1$	150 mm
$L_2$	24.5 mm
Shank height h	25 mm
Functional width $L_4$	30 mm
Application type	right-hand
Type of product	Clamping toolholder

---

## Accessories

Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
Clamping screw	279910
PrecisionBit for Torx®, shank E 6.3 Torx® profile TX10	674248 TX10
Clamping screw Type 9	279815 9