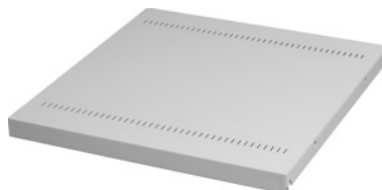


Garant GRIDLINE

**Storage shelf slotted, Front height: 50mm****Order data**

Order number	935111 50
GTIN	4062406111298
Item class	9GK

**Description****Version:**

Made of sheet metal with cross-bracing on the underside. Standard storage shelf / top storage shelf for bolting in. **Loading capacity 200 kg.**

**Colour:**

Light grey RAL 7035, **powder-coated.**

**Note:**

- **The storage shelf also acts as the locking base in combination with the central locking No. 935590, 935595. Prepared for mounting cylinder locks in the fascia.**
- **25 mm high storage shelves cannot be combined with intermediate bridging rails and end rails.**

**Technical description**

Shelf load capacity / maximum distributed shelf load (on metal)	200 kg
Storage shelf version	slotted shelf
Storage shelf version	fixed shelf
Storage shelf version	straight shelf
Front height	50 mm
Application range	Drawer/shelf combination unit
Material thickness	1.2 mm

Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Width	703 mm
Depth	575 mm
Width in G	26
Depth in G	20
Type of product	Storage shelf