


Garant GRIDLINE

## Storage shelf slotted, Front height: 25mm

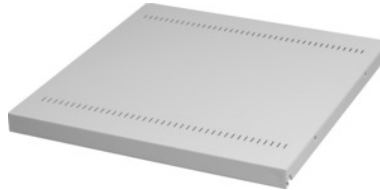

### Order data

Order number	935131 25
GTIN	4062406111380
Item class	9GK

### Description

#### Version:

Made of sheet metal with cross-bracing on the underside. Standard storage shelf for insertion.

#### Load capacity 150 kg.

#### Colour:

Light grey RAL 7035, powder-coated.

#### Note:

- The storage shelf also acts as the locking base in combination with the central locking No. 935590, 935595. Prepared for mounting cylinder locks in the fascia.
- 25 mm high storage shelves cannot be combined with intermediate bridging rails and end rails.

### Technical description

Front height	25 mm
Shelf load capacity / maximum distributed shelf load (on metal)	150 kg
Storage shelf version	slotted shelf
Storage shelf version	straight shelf
Storage shelf version	fixed shelf
Application range	Drawer/shelf combination unit
Material thickness	1.2 mm

Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Width	703 mm
Depth	675 mm
Width in G	26
Depth in G	24
Type of product	Storage shelf