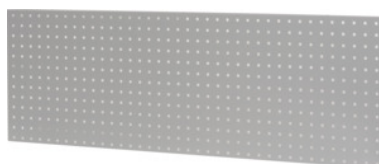


**Garant****Perforated panel single-sided, suitable for type: 2000****Order data**

Order number	928070 2000
GTIN	4062406112684
Item class	91P

**Description****Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage.

Perforated panels made of folded sheet metal  $\square$  9x9 mm at 37 mm intervals for mounting perforated panel accessories.

**Suitable for:**

For bolting between the support columns No. 928010, in materials supply trolley No. 918590 and for divider walls No. 955430 and 955431.

**Colour:**

RAL 7035 light grey **powder coated**.

**Note:**

See group 95 for accessories for perforated back panels.

**Technical description**

Perforated panel version	single-sided
Depth	25 mm
Safe working load	100 kg
Height	481 mm
Width	1920 mm
Weight	12 kg
suitable for type	2000 mm

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated rear panel

## Accessories

Multimedia swivel arm with multi-function mounting Number of joints 2	928270 2
Support column for hooking into perforated panel Height 481 mm	928060 481
Multimedia swivel arm with multi-function mounting Number of joints 1	928270 1
Multifix suitable for type 500	928201 500
Multimedia swivel arm with notebook holder Number of joints 2	928275 2
Multifix suitable for type 300	928201 300
Multifix suitable for type 1500	928201 1500