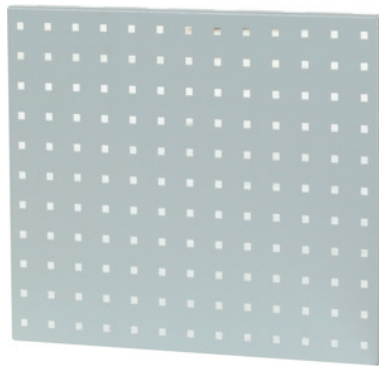


Garant**Perforated panel single-sided, suitable for type: 500****Order data**

Order number	928070 500
GTIN	4062406112653
Item class	91P

Description**Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage.

Perforated panels made of folded sheet metal \square 9x9 mm at 37 mm intervals for mounting perforated panel accessories.

Suitable for:

For bolting between the support columns No. 928010, in materials supply trolley No. 918590 and for divider walls No. 955430 and 955431.

Colour:

RAL 7035 light grey **powder coated**.

Note:

See group 95 for accessories for perforated back panels.

Technical description

Safe working load	100 kg
Depth	25 mm
suitable for type	500 mm

Width	420 mm
Height	481 mm
Weight	3 kg
Perforated panel version	single-sided
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated rear panel

Accessories

Multimedia swivel arm with multi-function mounting Number of joints 1	928270 1
Multimedia swivel arm with notebook holder Number of joints 2	928275 2
Multimedia swivel arm with multi-function mounting Number of joints 2	928270 2
Support column for hooking into perforated panel Height 481 mm	928060 481
Multifix suitable for type 300	928201 300