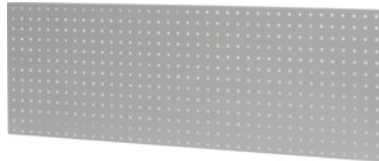


**Garant****Perforated panel double-sided, suitable for type: 2000****Order data**

Order number	928071 2000
GTIN	4062406113018
Item class	91P

**Description****Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage.

Perforated panel in **double-sided version** can be **independently equipped** on both sides.

Perforated panels made of folded sheet metal  $\square$  9x9 mm at 37 mm intervals for mounting perforated panel accessories.

**Suitable for:**

For bolting between the support columns No. 928010, in materials supply trolley No. 918590 and for divider walls No. 955430 and 955431.

**Colour:**

RAL 7035 light grey **powder coated**.

**Note:**

See group 95 for accessories for perforated back panels.

**Technical description**

Perforated panel version	double-sided
Depth	25 mm
Width	1920 mm
Safe working load	100 kg
suitable for type	2000 mm
Weight	24 kg

Height	481 mm
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated rear panel

## Accessories

Multimedia swivel arm with multi-function mounting Number of joints 1	928270 1
Multifix suitable for type 1000	928201 1000
Multifix suitable for type 1500	928201 1500
Support column for hooking into perforated panel Height 481 mm	928060 481
Multimedia swivel arm with notebook holder Number of joints 2	928275 2
Multimedia swivel arm with multi-function mounting Number of joints 2	928270 2
Multifix suitable for type 500	928201 500
Multifix suitable for type 300	928201 300