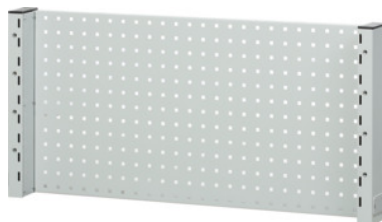


**Garant**

**Perforated rear panel (pair support columns + 1 perforated panel single-sided), Height 481 mm, suitable for type: 1500**

**Order data**

Order number	928075 1500
GTIN	4062406113032
Item class	91P

**Description****Version:**

Pair of support columns of steel hollow section 100×40×2 mm. **Insertion slots** at 50-mm intervals on the front face, together with **threaded sockets** on the front face to accept other modules / components. Perforated sheet metal panel between the columns.

**Application:**

**For screwing to worktops** of lengths 1000, 1500, and 2000 mm.

**Supplied with:**

Consisting of **1×** pair support columns + **1×** perforated panel on one side. Support arm brackets and cross braces cannot be mounted.

**Colour:**

RAL 7035 light grey **powder coated**.

**Technical description**

Height	481 mm
Perforated panel version	single-sided
suitable for type	1500 mm
Safe working load	100 kg
Design version	Steel hollow section construction

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Height adjustment interval	50 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Height 481 mm
Type of product	Perforated rear panel

---

## Accessories

Connector for support column Type 2	938027 2
Connector for support column Type 1	938027 1
Perforated panelsingle-sided suitable for type 1500	928070 1500
Support columns Height 481 mm	928010 481