


Garant

Perforated rear panel (pair support columns + 1 perforated panel single-sided), Height 481 mm, suitable for type: 1000

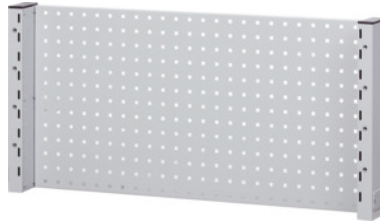

Order data

Order number	928075 1000
GTIN	4062406113025
Item class	91P

Description

Version:

Pair of support columns of steel hollow section 100×40×2 mm. **Insertion slots** at 50-mm intervals on the front face, together with **threaded sockets** on the front face to accept other modules / components. Perforated sheet metal panel between the columns.

Application:

For screwing to worktops of lengths 1000, 1500, and 2000 mm.

Supplied with:

Consisting of **1×** pair support columns + **1×** perforated panel on one side. Support arm brackets and cross braces cannot be mounted.

Colour:

RAL 7035 light grey **powder coated**.

Technical description

Safe working load	100 kg
Perforated panel version	single-sided
suitable for type	1000 mm
Height	481 mm
Design version	Steel hollow section construction

Data sheet

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Height adjustment interval	50 mm
Colour selection	RAL 9002, 7035, 7016, 5012, 5005
Product name attribute	Height 481 mm
Type of product	Perforated rear panel

Suitable products

<https://www.hoffmann-group.com/GB/en/hom/p/928075-1000>