


Garant

Perforated rear panel (pair support columns + 1 perforated panel single-sided), Height 481 mm, suitable for type: 1000

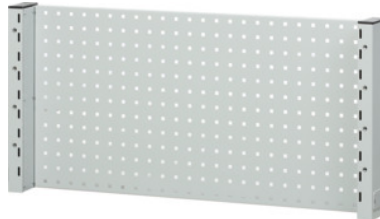

Order data

Order number	928075 1000
GTIN	4062406113025
Item class	91P

Description

Version:

Pair of support columns of steel hollow section 100×40×2 mm. **Insertion slots** at 50-mm intervals on the front face, together with **threaded sockets** on the front face to accept other modules / components. Perforated sheet metal panel between the columns.

Application:

For screwing to worktops of lengths 1000, 1500, and 2000 mm.

Supplied with:

Consisting of **1×** pair support columns + **1×** perforated panel on one side. Support arm brackets and cross braces cannot be mounted.

Colour:

RAL 7035 light grey **powder coated**.

Technical description

Safe working load	100 kg
Perforated panel version	single-sided
suitable for type	1000 mm
Height	481 mm
Design version	Steel hollow section construction

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Height adjustment interval	50 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Height 481 mm
Type of product	Perforated rear panel

Accessories

Connector for support column Type 2	938027 2
Connector for support column Type 1	938027 1
Support columns Height 481 mm	928010 481
Perforated panelsingle-sided suitable for type 1000	928070 1000