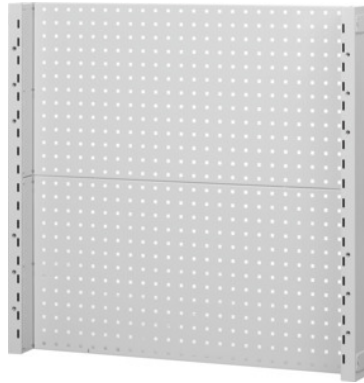


**Garant**

**Perforated rear panel (pair support columns + 2 perforated panels single-sided), Height 962 mm, suitable for type: 1000**

**Order data**

Order number	928076 1000
GTIN	4062406113056
Item class	91P

**Description****Version:**

Pair of support columns of steel hollow section 100×40×2 mm. **Insertion slots** at 50-mm intervals on the front face, together with **threaded sockets** on the front face to accept other modules / components. Perforated sheet metal panel between the columns.

**Application:**

**For screwing to worktops** of lengths 1000, 1500, and 2000 mm.

**Supplied with:**

Consisting of **1 pc.** pair support columns + **2 pcs.** perforated panel on one side. Suitable for mounting support arm brackets.

**Colour:**

RAL 7035 light grey **powder coated**.

**Technical description**

Safe working load	200 kg
Height	962 mm

Perforated panel version	single-sided
suitable for type	1000 mm
Design version	Steel hollow section construction
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Height adjustment interval	50 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Height 962 mm
Type of product	Perforated rear panel

---

## Accessories

Connector for support column Type 2	938027 2
Connector for support column Type 1	938027 1
Support columns Height 962 mm	928010 962
Perforated panelsingle-sided suitable for type 1000	928070 1000