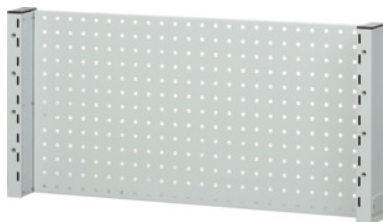


Garant

Perforated rear panel (pair support columns + 1 perforated panel single-sided), Height 481 mm, suitable for type: 2000

**Order data**

Order number	928075 2000
GTIN	4062406113049
Item class	91P

Description**NOTE: Colour selection possible****Version:**

Pair of support columns of steel hollow section 100×40×2 mm. **Insertion slots** at 50-mm intervals on the front face, together with **threaded sockets** on the front face to accept other modules / components. Perforated sheet metal panel between the columns.

Application:

For screwing to worktops of lengths 1000, 1500, and 2000 mm.

Supplied with:

Consisting of **1×** pair support columns + **1×** perforated panel on one side. Support arm brackets and cross braces cannot be mounted.

Colour:

RAL 7035 light grey **powder coated**.

Colour selection: RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003

Height: 481 mm

Safe working load: 100 kg

Technical description

Safe working load	100 kg
Height	481 mm

suitable for type	2000 mm
Perforated panel version	single-sided
Design version	Steel hollow section construction
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Height adjustment interval	50 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Height 481 mm
Type of product	Perforated rear panel

Accessories

Connector for support column Type 2	938027 2
Connector for support column Type 1	938027 1
Perforated panel single-sided suitable for type 2000	928070 2000
Support columns Height 481 mm	928010 481