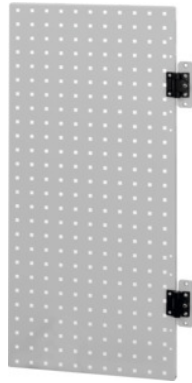


Garant**Pivoted perforated side panel, Height: 962mm****Order data**

Order number	928101 962
GTIN	4062406113155
Item class	91P

Description**Version:**

For bolting to the support columns, can be pivoted and secured with cast hinges. For clear and ergonomic storage of tools.

Suitable for:

Support column No. 928010 size 962, No. 928076.

Colour:

RAL 7035 light grey **powder coated**.

Technical description

Perforated panel version	single-sided
Depth	25 mm
Weight	6 kg
Width	420 mm
Height	962 mm
Safe working load	20 kg

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated rear panel