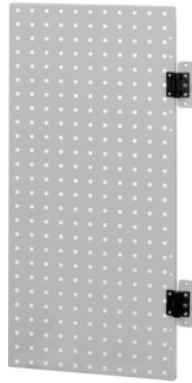


**Garant****Pivoted perforated side panel, Height: 481 mm****Order data**

Order number	928101 481
GTIN	4062406113148
Item class	91P

**Description****Version:**

For bolting to the support columns, can be pivoted and secured with cast hinges. For clear and ergonomic storage of tools.

**Suitable for:**

Support column No. 928010 size 481, No. 928075.

**Colour:**

RAL 7035 light grey **powder coated**.

**Technical description**

Height	481 mm
Depth	25 mm
Perforated panel version	single-sided
Safe working load	20 kg
Weight	3 kg
Width	420 mm

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated rear panel