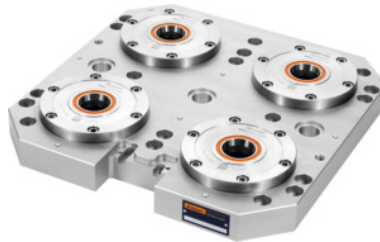


Garant**ZeroClamp base plate, Type: 21521****Order data**

Order number	360012 21521
GTIN	4045197722706
Item class	310

Description**Version:**

All bores for T-slot pitches of **63, 100, 125 mm**.

Centre bore \varnothing 25 H7 to receive a centring set. The zero point clamping of the GARANT ZeroClamp system is an important function for modern production systems, especially in automated production. Thanks to a special contact interface, it ensures precise and reliable zero point repetition accuracy. The pneumatic clamping force of the system holds workpieces securely in the desired position, making it possible to change workpieces quickly and accurately without repositioning. This reduces the set-up effort and increases productivity. The zero point clamping of the GARANT ZeroClamp system is indispensable for efficient production processes. Find out more about the innovative technology from GARANT ZeroClamp and optimise your production.

Application:

For vertical/horizontal machines.

Material:

Base plate of high-tensile aluminium, surface treated.

All components of the clamping pot of stainless or corrosion-resistant steel.

Optional extras:

Clamping stud No. 360025,

Connection block No. 360017 size 12808 / 12805.

Note:

Base plates with clamping pot dia. 138 mm are also available with self-locking clamping pots on request.

Technical description

Width B	396 mm
Height H	54 mm
Pitch S	200 mm
Number of clamping pots	4
Clamping pot Ø	138 mm
Type	21521
Length A	396 mm
Series	ZeroClamp
Type of product	Baseplate

Accessories

ZeroClamp connection block Type 12805	360017 12805
ZeroClamp clamping stud with internal thread Type 16M8	360025 16M8
ZeroClamp clamping stud with internal thread Type 18M12	360025 18M12
ZeroClamp clamping stud with internal thread Type 18M16/138	360025 18M16/138
ZeroClamp clamping stud with internal thread Type 25M16/138	360025 25M16/138
ZeroClamp cover plate for base plate Type 24311	360013 24311
ZeroClamp clamping stud with internal thread Type 12M10/90	360025 12M10/90
ZeroClamp clamping stud with internal thread Type 12M10	360025 12M10
ZeroClamp clamping stud with internal thread Type 18M16	360025 18M16
ZeroClamp clamping stud with internal thread Type 12M10/138	360025 12M10/138
ZeroClamp clamping stud with internal thread Type 16M10	360025 16M10
ZeroClamp clamping stud with internal thread Type 14M12/90	360025 14M12/90

ZeroClamp clamping stud with internal thread Type 25M10	360025 25M10
ZeroClamp clamping stud with internal thread Type 18M12/138	360025 18M12/138
ZeroClamp connection block Type 12808	360017 12808
ZeroClamp clamping stud with internal thread Type 25M10/138	360025 25M10/138