


Garant GRIDLINE

## Side cladding with media modules, Height: 550mm

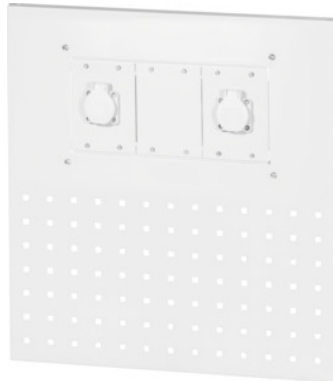

### Order data

Order number	928500 550
GTIN	4062406117306
Item class	9GG

### Description

#### Version:

Side panel for support leg of folded sheet steel, with perforations  $\square 9 \times 9$  mm in a 37 mm grid, to accept Easyfix hooks and holders, as well as perforated panel accessories.

Of sheet metal **modular design**. All power components include **cables** and **plugs**. The modules and covers can be changed / positioned as desired.

• Cable slots are provided on the upper, lower, and end faces for power supplies and for linking multiple media tracks together.

#### Electrical pre-installation with industrial plug-in system (applies only to media tracks):

1 pc. distribution block No. 928492 with 5-pin feed/supply cable and 5 pcs. 3-pin sockets,  
1 pc. 5-pin plug connector No. 928490 size 5 included for the feed cable.

#### Description:

#### Technical data for industrial plug-in system (No. 928490; 928491; 928492):

- **Maximum connection value 230 V / AC, 16 A or 400 V / AC, 16 A.**
- **Total load capacity at AC: 3.5 kW.**
- **Maximum connected load, three-phase AC: 10.5 kW.**
- **Conductor cross-section of the pre-assembled cables:**
  - 3 × 1.5 mm<sup>2</sup> for single-phase AC (L, N, PE)**
  - 5 × 1.5 mm<sup>2</sup> for three-phase AC (L1, L2, L3, N, PE)**
- **Protection class 1**
- **Index of Protection IP 20.**

**Suitable for:**

Workbenches height 850 mm, support legs height 800 mm and 650 mm.

**Fitted with:**

250 V socket No. 928470 size. DE250V/1: 2

No. of empty modules (1U / 2U / 3U): 1x / 0x / 0x

**Colour:**

RAL 7035 light grey **powder coated**.

**Note:**

See No. 928470 for other suitable media modules. The modules No. 928470 of sizes \_CEE400/5, \_AIR/S, \_STOP, \_ON/OFF1, \_ON/OFF2 and \_RCD cannot be incorporated in the side cladding. Initial connections and also the connection of plugs or sockets to cables should only be performed by a qualified electrician.

---

**Technical description**

Height	550 mm
Width	500 mm
Plug type, input	GST plug-in system
Nominal voltage	250 V
Number of sockets type F	2
Socket type	F
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Side cladding

---

**Accessories**

Module for energy and media Module type 0/2	928470 0/2
Module for energy and media Module type 0/1	928470 0/1