


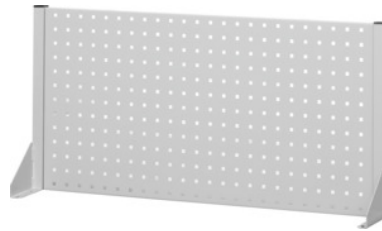

Perforated rear panel, Height 481 mm, suitable for type: 1000



Order data

| | |
|--------------|---------------|
| Order number | 929650 1000 |
| GTIN | 4062406118624 |
| Item class | 92W |

Description

Version:

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

Colour:

RAL 7035 light grey **powder coated**.

Note:

Articles in the support column attachment range cannot be inserted into the perforated panel.

Technical description

| | |
|---|-----------------------------------|
| suitable for type | 1000 mm |
| Perforated panel version | single-sided |
| Depth | 25 mm |
| Width | 920 mm |
| Height | 481 mm |
| Design version | Steel hollow section construction |
| Material thickness | 1 mm |
| Hoffmann perforated panel grid interval | 9×9 mm |
| Product name attribute | Height 481 mm |

Type of product

Perforated rear panel