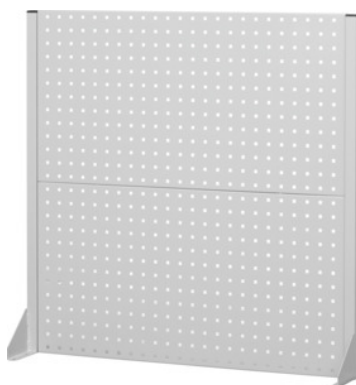


**HOLEX perforated rear panel, Height 962 mm, suitable for type: 1000****Order data**

Order number	929651 1000
GTIN	4062406118662
Item class	92W

Description**Version:**

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

Colour:

RAL 7035 light grey **powder coated**.

Note:

Articles in the support column attachment range cannot be inserted into the perforated panel.

Technical description

suitable for type	1000 mm
Width	920 mm
Depth	25 mm
Perforated panel version	single-sided
Height	962 mm
Design version	Steel hollow section construction

Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Product name attribute	Height 962 mm
Type of product	Perforated rear panel