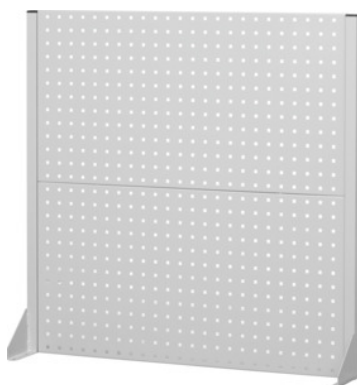


**HOLEX perforated rear panel, Height 962 mm, suitable for type: 1000****Order data**

Order number	929651 1000
GTIN	4062406118662
Item class	92W

**Description****Version:**

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

**Colour:**

RAL 7035 light grey **powder coated**.

**Note:**

Articles in the support column attachment range cannot be inserted into the perforated panel.

Hoffmann perforated panel grid interval: 9×9 mm

Height: 962 mm

Width: 920 mm

Depth: 25 mm

**Technical description**

suitable for type	1000 mm
Width	920 mm
Depth	25 mm

Height	962 mm
Design version	Steel hollow section construction
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Product name attribute	Height 962 mm
Type of product	Perforated backplate