


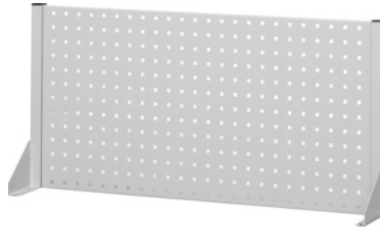

Perforated rear panel, Height 481 mm, suitable for type: 1500



Order data

Order number	929650 1500
GTIN	4062406118631
Item class	92W

Description

Version:

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

Colour:

RAL 7035 light grey **powder coated**.

Note:

Articles in the support column attachment range cannot be inserted into the perforated panel.

Technical description

suitable for type	1500 mm
Perforated panel version	single-sided
Height	481 mm
Width	1420 mm
Depth	25 mm
Design version	Steel hollow section construction
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Product name attribute	Height 481 mm

Type of product

Perforated rear panel