


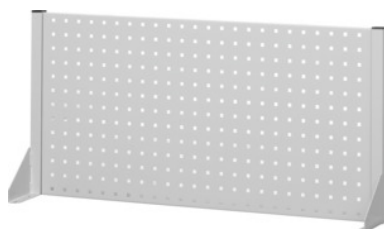

## Perforated rear panel, Height 481 mm, suitable for type: 2000



### Order data

Order number	929650 2000
GTIN	4062406118648
Item class	92W

### Description

#### Version:

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

#### Colour:

RAL 7035 light grey **powder coated**.

#### Note:

Articles in the support column attachment range cannot be inserted into the perforated panel. Hoffmann perforated panel grid interval: 9×9 mm

Height: 481 mm

Width: 1920 mm

Depth: 25 mm

### Technical description

Depth	25 mm
Width	1920 mm
Height	481 mm
suitable for type	2000 mm
Design version	Steel hollow section construction
Material thickness	1 mm

Hoffmann perforated panel grid interval	9×9 mm
Product name attribute	Height 481 mm
Type of product	Perforated backplate