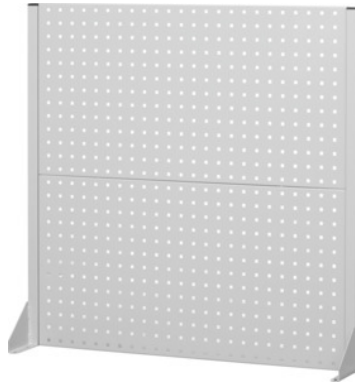


**HOLEX perforated rear panel, Height 962 mm, suitable for type: 1250****Order data**

| | |
|--------------|---------------|
| Order number | 929651 1250 |
| GTIN | 4062406118693 |
| Item class | 92W |

Description**Version:**

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

Colour:

RAL 7035 light grey **powder coated**.

Note:

Articles in the support column attachment range cannot be inserted into the perforated panel.

Technical description

| | |
|--------------------------|-----------------------------------|
| Perforated panel version | single-sided |
| Width | 1170 mm |
| Height | 962 mm |
| Depth | 25 mm |
| Design version | Steel hollow section construction |
| Material thickness | 1 mm |

| | |
|---|-----------------------|
| Hoffmann perforated panel grid interval | 9×9 mm |
| Product name attribute | Height 962 mm |
| Type of product | Perforated rear panel |