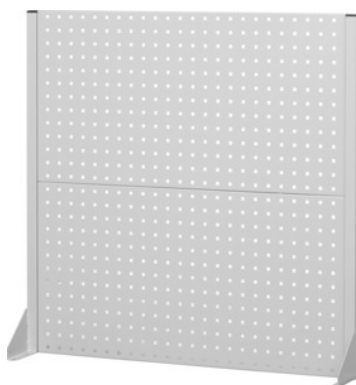


**HOLEX perforated rear panel, Height 962 mm, suitable for type: 2000****Order data**

Order number	929651 2000
GTIN	4062406118686
Item class	92W

Description**Version:**

Stand of sheet metal 40×40 mm for screwing to the worktop. Perforated sheet metal panel between the columns.

Colour:

RAL 7035 light grey **powder coated**.

Note:

Articles in the support column attachment range cannot be inserted into the perforated panel.

Hoffmann perforated panel grid interval: 9×9 mm

Height: 962 mm

Width: 1920 mm

Depth: 25 mm

Technical description

Depth	25 mm
Height	962 mm
suitable for type	2000 mm

Width	1920 mm
Design version	Steel hollow section construction
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm
Product name attribute	Height 962 mm
Type of product	Perforated backplate