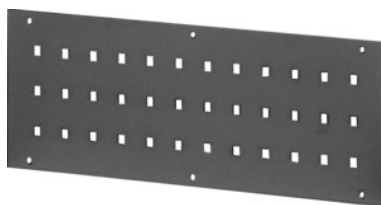


Garant**Perforated side panels 2 pieces, Type: 750****Order data**

Order number	920360 750
GTIN	4062406120795
Item class	91S

Description**Version:**

Made of folded sheet metal with \square 9×9 mm holes at 37 mm pitch.
For attachment to the sides of workstations with electric height adjustment, for light loads.
Perforated panels are bolted to cross braces from within. Set of 2 pieces.

Suitable for:

Workstations with electric height adjustment, for light loads No. 920301 – 920306.

Supplied with:

Fastening material.

Colour:

Anthracite RAL 7016 **powder-coated**.

Technical description

Height	146 mm
Weight	0.6 kg
Width	536 mm
Depth	73 mm
Material thickness	1 mm
Hoffmann perforated panel grid interval	9×9 mm

Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Side cladding