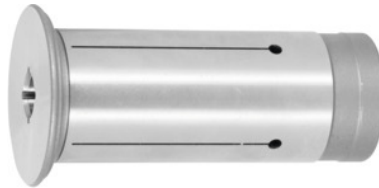


Garant**Slotted reducing adapter with cooling, Ø 20 mm, Clamping range Ø D1: 3mm****Order data**

Order number	302155 3
GTIN	4045197732637
Item class	31G

Description**Version:****With cooling channel slots.****Application:**

- **For drilling, reaming, milling, and tool sharpening.**
- **Very high flexibility due to reduction in clamping diameter.**
- **Very high torque guarantees a higher volume of metal removal compared to direct clamping.**
- **Concentricity $\pm 5 \mu\text{m}$ (system accuracy at $3 \times D$).**
- **Concentricity $\pm 2 \mu\text{m}$ (for reducing adapter).**
- **Can be used in all commercially available hydraulic chucks.**

Suitable for:Hydraulic chuck **with clamping Ø 20 mm.****Technical description**

Clamping Ø D ₁	3 mm
Ø D	20 mm
Product name attribute	Ø 20 mm
Concentricity system	5 μm
Type of product	Reducing adapter

