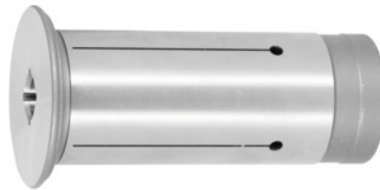


Garant
Slotted reducing adapter with cooling, Ø 20 mm, Clamping range Ø D1: 14mm

Order data

Order number	302155 14
GTIN	4045197732705
Item class	31G

Description
Version:

With cooling channel slots.

Application:

- For drilling, reaming, milling, and tool sharpening.
- Very high flexibility due to reduction in clamping diameter.
- Very high torque guarantees a higher volume of metal removal compared to direct clamping.
- Concentricity $\pm 5 \mu\text{m}$ (system accuracy at $3 \times D$).
- Concentricity $\pm 2 \mu\text{m}$ (for reducing adapter).
- Can be used in all commercially available hydraulic chucks.

Suitable for:

Hydraulic chuck with clamping Ø 20 mm.

Technical description

Ø D	20 mm
Clamping Ø D ₁	14 mm
Product name attribute	Ø 20 mm
Concentricity system	5 μm
Type of product	Reducing adapter

