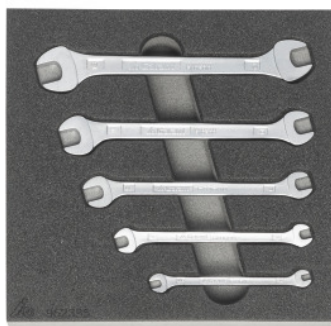


Garant
Double open ended spanner set, Number of tools: 5

Order data

Order number	952385 5
GTIN	4062406152611
Item class	91A

Description
Version:

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. **Upper layer is anthracite**, the underlying **contrast colour is grey**, thereby indicating any missing tools.

Supplied with:

Rigid foam inlay, empty No. 952001 size 952385: 1 pc.

GARANT double open-ended spanner No. 610600 size 4x5; 6x7; 8x9; 10x11; 12x13: 1 pc. each

Degree of fill of a drawer in units: 8x8

Width: 200 mm

Depth: 200 mm

Width in G: 8

Depth in G: 8

Technical description

Width	200 mm
Number of tools	5
Depth in G	8

Width in G	8
Depth	200 mm
Version	with spanners (ring spanners and open-ended spanners)
Weight	0.237 kg
Rigid foam quality LD45, thickness	30 mm
Degree of fill of a drawer in units	8×8
Type of product	Rigid foam inlay

Accessories

Double open ended spanner Jaw widths 12X13 mm	610600 12X13
Double open ended spanner Jaw widths 6X7 mm	610700 6X7
Double open ended spanner Jaw widths 4X5 mm	610600 4X5
Double open ended spanner Jaw widths 10X11 mm	610600 10X11
Rigid foam inlay for tool sets suitable for rigid foam set 952385	952001 952385
Double open ended spanner Jaw widths 10X11 mm	610700 10X11
Double open ended spanner Jaw widths 6X7 mm	610600 6X7
Double open ended spanner Jaw widths 8X9 mm	610600 8X9
Double open ended spanner Jaw widths 8X9 mm	610700 8X9
Double open ended spanner Jaw widths 4X5 mm	610700 4X5
Double open ended spanner Jaw widths 12X13 mm	610700 12X13