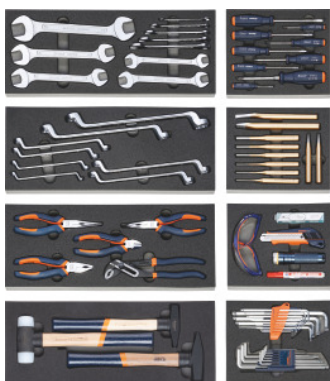


Garant
Tool organiser system set for 3 drawers, Type: G1

Order data

| | |
|--------------|---------------|
| Order number | 955051 G1 |
| GTIN | 4062406158446 |
| Item class | 91A |

Description
Version:

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. Upper layer anthracite, under which the contrast colour of blue indicates if a tool is missing.

The rigid foam inlays fill 1/4 (10 G × 8 G or 250 × 200 mm) or 1/2 (20 G × 8 G or 500 × 200 mm) of the usable drawer area.

Suitable for :

GARANT roller cabinets with full extension drawers and a drawer module of **20 G × 16 G** or 500 × 400 mm (W × D).

Roller cabinets No. 914520 – 914582.

Supplied with:

Double open-ended spanner set No. 952422 size 10: 1 pc.

Double-ended ring spanner set No. 952443 size 8: 1 pc.

Screwdriver set No. 953391 size 9: 1 pc.

Pliers set No. 954201 size 5: 1 pc.

Hammer set No. 954665 size 3: 1 pc.

Chisel, taper pin punch, pin punch set No. 954652 size 10: 1 pc.

Workshop accessory set No. 954852 size 5: 1 pc.

Hexagon key L-wrenches for Torx® No. 953141 size 22: 1 pc.

suitable for workstations and storage equipment: Roller cabinet

Technical description

| | |
|---|---------------------------|
| Version | for roller cabinet drawer |
| suitable for drawer front height | 75 mm |
| suitable for drawer front height | 125 mm |
| suitable for drawer front height | 200 mm |
| Degree of fill of a drawer in units | 20×16 |
| suitable for workstations and storage equipment | Roller cabinet |
| Type of product | Rigid foam inlay |

Accessories

| | |
|---|---------------|
| Rigid foam inlay for tool sets suitable for rigid foam set 952443 | 952001 952443 |
| LED torches with batteries Type 130 mm | 081505 130 |
| Screwdriver for Phillips, with 2-component Haptoprene handle Cross-head size 0 | 667690 0 |
| Pin punch, standard quality, painted Point Ø D 2 mm | 747000 2 |
| Double-ended ring spanner, deeply cranked Width across flats 14X17 mm | 615700 14X17 |
| Double-ended ring spanner, deeply cranked Width across flats 12X13 mm | 615700 12X13 |
| Double-ended ring spanner, deeply cranked Width across flats 19X22 mm | 615700 19X22 |
| Rigid foam inlay for tool sets suitable for rigid foam set 952422 | 952001 952422 |
| Rigid foam inlay for tool sets suitable for rigid foam set 953141 | 952001 953141 |
| Hexagon key L-wrench set, with retainer ball chrome-plated Number of screwdrivers 9 | 627132 9 |
| Combination pliers, chrome-plated, with 2-component grips overall length 180 mm | 700940 180 |

| | |
|--|---------------|
| Double-ended ring spanner, deeply cranked Width across flats 8X9 mm | 615700 8X9 |
| Screwdriver for Phillips, with 2-component Haptoprene handle Cross-head size 1 | 667690 1 |
| Double-ended ring spanner, deeply cranked Width across flats 10X11 mm | 615700 10X11 |
| Rigid foam inlay for tool sets suitable for rigid foam set 954652 | 952001 954652 |
| Screwdriver for slot-head, with 2-component Haptoprene handle Blade width b 2,5 mm | 660030 2,5 |
| Cross-cut cold chisel overall length 200 mm | 740600 200 |
| Flat cold chisel overall length 200 mm | 740500 200 |
| Double-ended ring spanner, deeply cranked Width across flats 24X27 mm | 615700 24X27 |
| Rigid foam inlay for tool sets suitable for rigid foam set 954201 | 952001 954201 |
| Rigid foam inlay for tool sets suitable for rigid foam set 954665 | 952001 954665 |
| Double-ended ring spanner, deeply cranked Width across flats 16X18 mm | 615700 16X18 |
| General-purpose knife with 2-component handle with 3 blades, 18 mm | 845020 |
| Pin punch, standard quality, painted Point Ø D 5 mm | 747000 5 |
| Screwdriver for Phillips, with 2-component Haptoprene handle Cross-head size 00 | 667690 00 |
| Snipe nose pliers, straight, chrome-plated, with grips overall length 200 mm | 713040 200 |
| Double open ended spanner set Number of keys 10 | 610610 10 |
| Dead-blow hammer with nylon inserts Hickory handle Hammer head Ø 40 mm | 754750 40 |
| Screwdriver for slot-head, with 2-component Haptoprene handle Blade width b 4 mm | 660030 4 |
| Snipe nose pliers, angled, chrome-plated, with grips overall length 200 mm | 713440 200 |

| | |
|---|---------------|
| Water pump pliers with stepped fine adjustment, black overall length 250 mm | 706000 250 |
| Screwdriver for slot-head, with 2-component Haptoprene handle Blade width b 5,5 mm | 660030 5,5 |
| Pin punch, standard quality, painted Point Ø D 8 mm | 747000 8 |
| Screwdriver for slot-head, with 2-component Haptoprene handle Blade width b 3,5 mm | 660030 3,5 |
| Water pump pliers with stepped fine adjustment, black overall length 250 mm | 706001 250 |
| Engineer's hammer with handle protection collar Weight without handle 300 g | 750110 300 |
| Taper pin punch heavy version Tip Ø 4 mm | 745500 4 |
| Rigid foam inlay for tool sets suitable for rigid foam set 953391 | 952001 953391 |
| Comfort safety glasses uvex i-vo Lens tinting CLEAR | 096515 CLEAR |
| Torx® key L-wrench set, with MagicSpring® retainer function Number of screwdrivers 13 | 625025 13 |
| Engineer's hammer with handle protection collar Weight without handle 500 g | 750110 500 |
| Screwdriver for Phillips, with 2-component Haptoprene handle Cross-head size 2 | 667690 2 |
| Pin punch, standard quality, painted Point Ø D 4 mm | 747000 4 |
| Taper pin punch heavy version Tip Ø 3 mm | 745500 3 |
| Double-ended ring spanner, deeply cranked Width across flats 6X7 mm | 615700 6X7 |
| Screwdriver for slot-head, with 2-component Haptoprene handle Blade width b 2 mm | 660030 2 |
| Pin punch, standard quality, painted Point Ø D 6 mm | 747000 6 |
| Rigid foam inlay for tool sets suitable for rigid foam set 954852 | 952001 954852 |
| LED torches with batteries Type 125 mm | 081505 125 |
| Permanent marker Writing colour R | 085130 R |
| Pin punch, standard quality, painted Point Ø D 3 mm | 747000 3 |

| | |
|---|--------------|
| Double open ended spanner Jaw widths 14X15 mm | 610600 14X15 |
| Double open ended spanner Jaw widths 6X7 mm | 610600 6X7 |
| Double-ended ring spanner, deeply cranked Width across flats 16X18 mm | 615600 16X18 |
| Double open ended spanner Jaw widths 21X24 mm | 610600 21X24 |
| Diagonal side cutter chrome-plated, with grips overall length 160 mm | 724840 160 |
| Double open ended spanner Jaw widths 10X11 mm | 610600 10X11 |
| Double-ended ring spanner, deeply cranked Width across flats 14X17 mm | 615600 14X17 |
| Double open ended spanner Jaw widths 27X30 mm | 610600 27X30 |
| Double-ended ring spanner, deeply cranked Width across flats 16X18 mm | 615950 16X18 |
| Double-ended ring spanner, deeply cranked Width across flats 12X13 mm | 615000 12X13 |
| Double open ended spanner Jaw widths 20X22 mm | 610600 20X22 |
| Double-ended ring spanner, deeply cranked Width across flats 8X9 mm | 615600 8X9 |
| Double-ended ring spanner, deeply cranked Width across flats 10X11 mm | 615600 10X11 |
| Double-ended ring spanner, deeply cranked Width across flats 10X11 mm | 615000 10X11 |
| Double-ended ring spanner, deeply cranked Width across flats 6X7 mm | 615600 6X7 |
| Double-ended ring spanner, deeply cranked Width across flats 24X27 mm | 615000 24X27 |
| Double open ended spanner Jaw widths 8X9 mm | 610600 8X9 |
| Snap-off "experience" blades set, 10 pieces, 18 mm number 10 | 845010 10 |
| Double-ended ring spanner, deeply cranked Width across flats 24X27 mm | 615600 24X27 |
| Double open ended spanner Jaw widths 16X17 mm | 610600 16X17 |
| Double open ended spanner Jaw widths 18X19 mm | 610600 18X19 |

| | |
|---|--------------|
| Double-ended ring spanner, deeply cranked Width across flats 19X22 mm | 615600 19X22 |
| Double-ended ring spanner, deeply cranked Width across flats 12X13 mm | 615600 12X13 |
| Double open ended spanner Jaw widths 12X13 mm | 610600 12X13 |