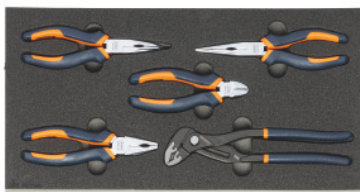


**Garant**
**Pliers set, Number of tools: 5**

**Order data**

Order number	954295 5
GTIN	4062406157654
Item class	91A

**Description**
**Version:**

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. **Upper layer anthracite**, under which the **contrast colour** of blue indicates if a tool is missing.

The rigid foam inlays fill 1/4 (10 G × 10 G or 250 × 250 mm) or 1/2 (10 G × 20 G or 250 × 500 mm) of the usable drawer area.

**Suitable for :**

New GARANT GridLine workbenches with full extension drawers and a new drawer module of 20 G × 20 G or 500 × 500 mm (W × D).

**Supplied with:**

Rigid foam inlay, empty No. 952001 size 954295: 1 pc.

GARANT combination pliers No. 700940 size 180: 1 pc.

GARANT water pump pliers No. 706001 size 250: 1 pc.

GARANT snipe-nose pliers No. 713040 size 200: 1 pc.

GARANT snipe-nose pliers, angled No. 713440 size 200: 1 pc.

GARANT side cutter No. 724840 size 160: 1 pc.

Degree of fill of a drawer in units: 10×20

Width: 250 mm

Depth: 500 mm

Width in G: 10

Depth in G: 20

**Technical description**

Number of tools	5
Width in G	10
Width	250 mm
Depth in G	20
Depth	500 mm
Weight	1.553 kg
Rigid foam quality LD45, thickness	30 mm
Degree of fill of a drawer in units	10×20
Type of product	Rigid foam inlay

## Accessories

Snipe nose pliers, straight, chrome-plated, with grips overall length 200 mm	713040 200
Rigid foam inlay for tool sets suitable for rigid foam set 954295	952001 954295
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706000 250
Combination pliers, chrome-plated, with 2-component grips overall length 180 mm	700940 180
Snipe nose pliers, angled, chrome-plated, with grips overall length 200 mm	713440 200
Diagonal side cutter chrome-plated, with grips overall length 160 mm	724840 160
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706001 250