


## Non-slip mat, closed 10 m roll, Depth: 750mm

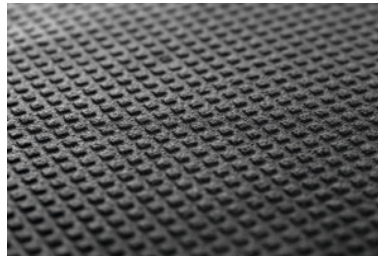

### Order data

Order number	951908 750
GTIN	4063104000440
Item class	96M

### Description

**Version:**

Mat with structured surface of PES/glass fibre fabric, coated on both sides with non-slip PVC foam. Very good non-slip and tear resistance characteristics. Anthracite colour.

**Application:**

For insertion into drawers. As protection against slipping and for protective storage of tools.

**Standard:**

DIN EN 597-1/6.4 (Entflammbarkeitsprüfung); VDI 2700:2009/Blatt 15/Punkt 11.3 (Verformungs- und Eindrucksverhalten). REACH-Vorschriften werden erfüllt.

**Note:**

No adhesive/non-slip effect when wet.

### Technical description

Length	10000 mm
Depth	750 mm
Version	Goods by the metre
Manufacturer's designation	T-Tec non-slip roll 0.75 x 10 m
Thickness	2.5 mm
Type of product	Anti-slip mat

