




Pitbull clamp blunt edge, Thread M: M4

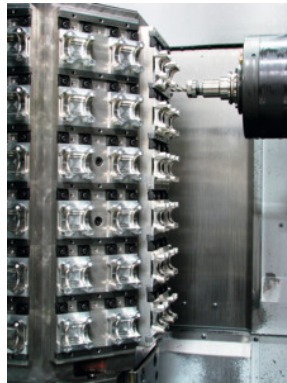

Order data

Order number	370030 M4
GTIN	4046368563302
Item class	37M

Description

Version:

- **Clamp with socket-head screw to DIN912, with oil-tight O-ring.**
- **Secure and precise clamping.**
- **Compact size, so few interference contours.**

Blunt edge for general tasks.

Application:

Ideal for multiple clamping.

B_{H9} : 12.7 mm

H: 9.9 mm

B_1 : 5.1 mm

H_1 : 4.8 mm

Height H_2 : 2.6 mm

Clamping width: 12.7 mm

Technical description

Clamping travel	0.4 mm
Material	Steel

Clamping width	12.7 mm
H ₁	4.8 mm
Clamping force	6.6 kN
B _{H9}	12.7 mm
Thread M	M4
H	9.9 mm
Height H ₂	2.6 mm
B ₁	5.1 mm
maximum tightening torque	5.6 N·m
Type of product	Jig clamping system