




Pitbull clamp knife edge, Thread M: M6

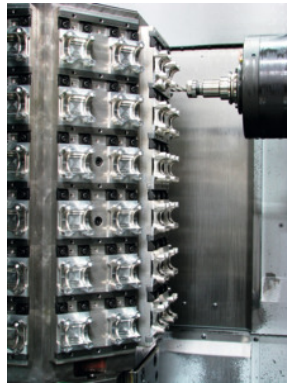

Order data

| | |
|--------------|---------------|
| Order number | 370025 M6 |
| GTIN | 4046368563500 |
| Item class | 37M |

Description

Version:

- **Clamp with socket-head screw to DIN912, with oil-tight O-ring.**
- **Secure and precise clamping.**
- **Compact size, so few interference contours.**

Knife edge for blanks.

Application:

Ideal for multiple clamping.

Technical description

| | |
|-----------------|---------|
| Clamping width | 19.1 mm |
| Clamping force | 16 kN |
| Thread M | M6 |
| Clamping travel | 0.6 mm |
| B ₁ | 7.6 mm |
| H ₁ | 7.2 mm |

| | |
|---------------------------|---------------------|
| B _{H9} | 19.05 mm |
| Material | Steel |
| Height H ₂ | 3.8 mm |
| H | 14.48 mm |
| maximum tightening torque | 22.5 Nm |
| Type of product | Jig clamping system |