




Pitbull clamp blunt edge, Thread M: M6

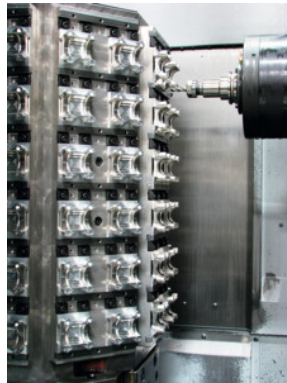

Order data

Order number	370030 M6
GTIN	4046368563609
Item class	37M

Description

Version:

- **Clamp with socket-head screw to DIN912, with oil-tight O-ring.**
- **Secure and precise clamping.**
- **Compact size, so few interference contours.**

Blunt edge for general tasks.

Application:

Ideal for multiple clamping.

B_{H9} : 19.05 mm

H: 14.48 mm

B_1 : 7.6 mm

H_1 : 7.2 mm

Height H_2 : 3.8 mm

Clamping width: 19.1 mm

Technical description

Height H_2	3.8 mm
H	14.48 mm

Clamping travel	0.6 mm
Clamping force	16 kN
B_{H9}	19.05 mm
H_1	7.2 mm
Material	Steel
B_1	7.6 mm
Clamping width	19.1 mm
Thread M	M6
maximum tightening torque	22.5 N·m
Type of product	Jig clamping system