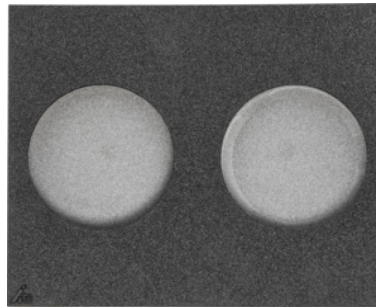


Garant GRIDLINE

Rigid foam inlays empty, for Hainbuch clamping heads, for collets: SK80**Order data**

Order number	970725 SK80
GTIN	4062406166281
Item class	91A

Description**Version:**

Two-colour rigid PE foam inlay (anthracite / grey, empty) with milled pockets to accept individual Hainbuch clamping heads. The closed-pore foam is **oil-resistant** and does not absorb liquids of any sort. The rigid foam inlays **fill 8x10G** of the usable drawer area.

Note:

Size TOP65 also suitable for SK65.

Technical description

Number of tool sockets	2
Degree of fill of a drawer in units	8x10
Depth in G	10
Width	200 mm
Width in G	8
Depth	250 mm
Rigid foam quality LD45, thickness	30 mm
Type of product	Rigid foam inlay

