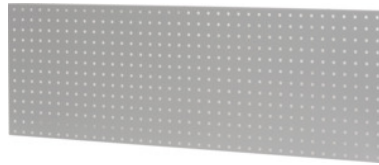


Garant GRIDLINE

ESD perforated panel single-sided, suitable for type: 2000**Order data**

| | |
|--------------|---------------|
| Order number | 972100 2000 |
| GTIN | 4062406167394 |
| Item class | 9GW |

Description**Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage. Perforated panel in **double-sided version** can be **independently equipped** on both sides. Perforated panels made of sheet metal $\square 9 \times 9$ mm at 37 mm intervals for mounting perforated panel accessories from Group 95.

Suitable for:

For **bolting** between ESD support columns No. 972080 and ESD materials supply trolley No. 972060 (only size 1000).

Colour:

Light grey similar to RAL 7035 **ESD powder-coated**.

Note:

All plastic components (e.g. covering caps) and handles are not ESD conductive.

Technical description

| | |
|--------------------------|--------------|
| Width | 1920 mm |
| Height | 481 mm |
| Safe working load | 100 kg |
| Weight | 12 kg |
| Depth | 25 mm |
| Perforated panel version | single-sided |
| Material thickness | 1 mm |

| | |
|---|-----------------------|
| Hoffmann perforated panel grid interval | 9×9 mm |
| electrostatic characteristic | EGB/ESD |
| Type of product | Perforated rear panel |