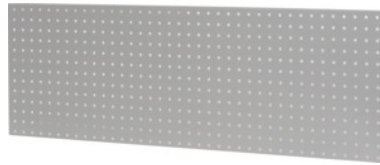


Garant GRIDLINE

**ESD perforated panel double-sided, suitable for type: 2000****Order data**

Order number	972101 2000
GTIN	4062406167424
Item class	9GW

**Description****Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage. Perforated panel in **double-sided version** can be **independently equipped** on both sides. Perforated panels made of sheet metal  $\square 9 \times 9$  mm at 37 mm intervals for mounting perforated panel accessories from Group 95.

**Suitable for:**

For **bolting** between ESD support columns No. 972080 and ESD materials supply trolley No. 972060 (only size 1000).

**Colour:**

Light grey similar to RAL 7035 **ESD powder-coated**.

**Note:**

All plastic components (e.g. covering caps) and handles are not ESD conductive.

**Technical description**

Weight	24 kg
Height	481 mm
Depth	25 mm
Perforated panel version	double-sided
Safe working load	100 kg
Width	1920 mm
Material thickness	1 mm

Hoffmann perforated panel grid interval	9×9 mm
electrostatic characteristic	EGB/ESD
Type of product	Perforated rear panel