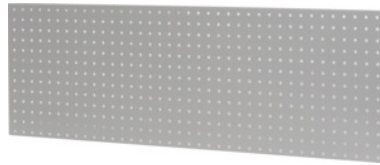


Garant GRIDLINE

ESD perforated panel single-sided, suitable for type: 1000**Order data**

Order number	972100 1000
GTIN	4062406167370
Item class	9GW

Description**Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage. Perforated panel in **double-sided version** can be **independently equipped** on both sides. Perforated panels made of sheet metal $\square 9 \times 9$ mm at 37 mm intervals for mounting perforated panel accessories from Group 95.

Suitable for:

For **bolting** between ESD support columns No. 972080 and ESD materials supply trolley No. 972060 (only size 1000).

Colour:

Light grey similar to RAL 7035 **ESD powder-coated**.

Note:

All plastic components (e.g. covering caps) and handles are not ESD conductive.

Technical description

Perforated panel version	single-sided
Width	920 mm
Depth	25 mm
Height	481 mm
Safe working load	100 kg
Weight	6 kg
Material thickness	1 mm

Hoffmann perforated panel grid interval	9×9 mm
electrostatic characteristic	EGB/ESD
Type of product	Perforated rear panel