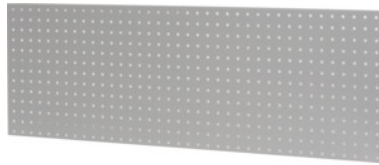


Garant GRIDLINE

**ESD perforated panel single-sided, suitable for type: 1500****Order data**

|              |               |
|--------------|---------------|
| Order number | 972100 1500   |
| GTIN         | 4062406167387 |
| Item class   | 9GW           |

**Description****Version:**

Of sturdy sheet metal, inclined for clean organisation of tool storage. Perforated panel in **double-sided version** can be **independently equipped** on both sides. Perforated panels made of sheet metal  $\square 9 \times 9$  mm at 37 mm intervals for mounting perforated panel accessories from Group 95.

**Suitable for:**

For **bolting** between ESD support columns No. 972080 and ESD materials supply trolley No. 972060 (only size 1000).

**Colour:**

Light grey similar to RAL 7035 **ESD powder-coated**.

**Note:**

All plastic components (e.g. covering caps) and handles are not ESD conductive.

**Technical description**

|                          |              |
|--------------------------|--------------|
| Width                    | 1420 mm      |
| Height                   | 481 mm       |
| Depth                    | 25 mm        |
| Safe working load        | 100 kg       |
| Weight                   | 9 kg         |
| Perforated panel version | single-sided |
| Material thickness       | 1 mm         |

|   |                       |
|---|-----------------------|
| Hoffmann perforated panel grid interval | 9×9 mm                |
| electrostatic characteristic            | EGB/ESD               |
| Type of product                         | Perforated rear panel |