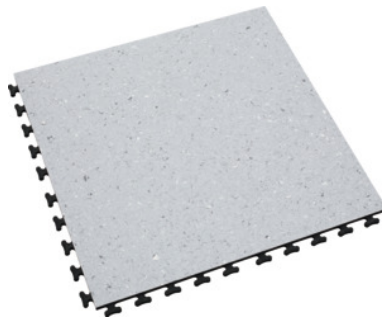


ESD floor panel, Colour: LIGHTGREY**Order data**

Order number	972585 LIGHTGREY
GTIN	4057989080000
Item class	98E

Description**Version:**

PVC panels each with 2 sides of positive and 2 sides of negative tooting. Discharge resistance approx. $10^6 \Omega$. Smooth surface and dissipative under layer with honeycomb structure.

Suitable for industrial trucks, pallet trucks and forklift trucks: up to a total weight of 2.5 t for hard tyres, up to 5 t for pneumatic tyres. Static: 50 kg/cm².

The special design of the floor panels allows quick installation of large areas of dissipative industrial floors. They can be used on all hard subfloors (they should only be relatively flat; worn and damp floors are possible) and on carpets with minimal or no preparation. Pale grey marbled.

Note:

Grounding the flooring via copper cable No. 972591 and grounding kit No. 972590. Please order these separately. Connection of the grounding must be performed by a specialist.

Technical description

Material	PVC
Length	60.8 cm
Thickness	10.5 mm
Width	60.8 cm
Weight	4.5 kg

ESD security	yes
Surface	smooth
Discharge resistance	10 ⁶ Ω
Colour	pale grey marbled
electrostatic characteristic	EGB/ESD
Type of product	ESD floor mat