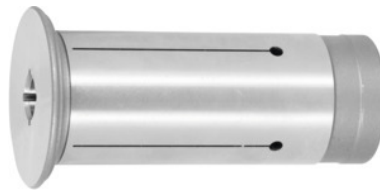


Garant

Slotted reducing adapter with cooling, Ø 12 mm, Clamping range Ø D1: 8mm


Order data

| | |
|--------------|---------------|
| Order number | 302135 8 |
| GTIN | 4045197763235 |
| Item class | 31G |

Description
Version:

With cooling channel slots.

Application:

- **For drilling, reaming, milling, and tool sharpening.**
- **Very high flexibility due to reduction in clamping diameter.**
- **Very high torque guarantees a higher volume of metal removal compared to direct clamping.**
- **Concentricity $\pm 5 \mu\text{m}$ (system accuracy at $3 \times D$).**
- **Concentricity $\pm 2 \mu\text{m}$ (for reducing adapter).**
- **Can be used in all commercially available hydraulic chucks.**

Suitable for:

Hydraulic chuck **with clamping Ø 12 mm.**

Technical description

| | |
|---------------------------|------------------|
| Ø D | 12 mm |
| Overall length L | 47 mm |
| Clamping Ø D ₁ | 8 mm |
| Product name attribute | Ø 12 mm |
| Concentricity system | 5 μm |
| Type of product | Reducing adapter |

